

Vue d'ensemble

- Male straight
- M12 , 4-pole, D-coded
- 0,14 - 0,34mm², 4,5 - 8,8mm, shielded



Caractéristiques techniques

Side A

Head A: Connection	M12
Head A: Angle cable outlet	0°
Head A: Gender	Male
Head A: Coding	D
Head A: Shielded	Oui
Head A: No. of poles	4
Head A: Tightening torque	0,6 Nm
Head A: Knurled nut material	GD-Zn,Ni
Head A: Body color	Black
Head A: Gasket material	Elastomer
Min. AWG	22
Max. AWG	26

Side A

Connection method	IDC terminal
Wire cross section (max.)	0,34 mm ²
Wire cross section (min.)	0,14 mm ²
Cable diameter (max.)	8,8 mm
Cable diameter (min.)	4,5 mm

Données électriques

Operating voltage	max. 50 V AC/DC 0
Operating current per contact	max. 4 A

Données mécaniques


Head A: Degree of protection	IP65, IP67
------------------------------	------------

Commercial data

Eclass	27440102
--------	----------

Side A

Technical drawing

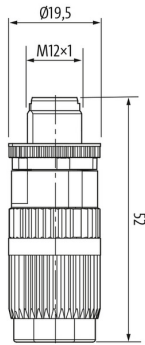

Coding

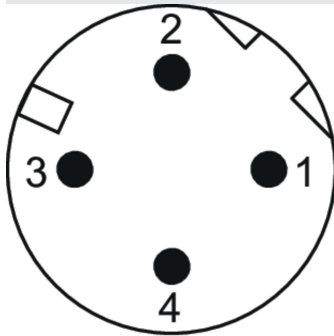


Schéma de raccordement

