

Overview

- M8, female, 4 poles; M8, male, 3 poles
- Head A: IP67; Head B: IP67
- Material: PUR



Technical data

Side A

Head A: Connection	M8
Head A: Angle cable outlet	0°
Head A: Gender	Female
Head A: Coding	A
Head A: No. of poles	4
Head A: Tightening torque	0.6 Nm

Side B

Head B: Connection	M8
Head B: Angle cable outlet	0°
Head B: Gender	Male
Head B: Coding	A
Head B: No. of poles	3

Side B

Head B: Tightening torque	0.6 Nm
---------------------------	--------

Electrical data

Operating voltage	max. 50 V AC / 60 V DC
Operating current per contact	max. 4 A

Mechanical data


Head A: Degree of protection	IP67
Head B: Degree of protection	IP67

Environmental conditions

Temperature range (fixed)	- 25 ...+ 85 °C
---------------------------	-----------------


Side A

Coding

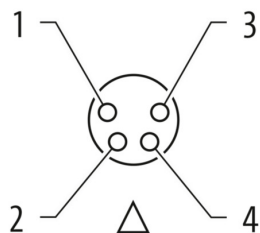


Side B

Coding

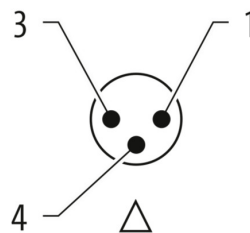

Connection diagram

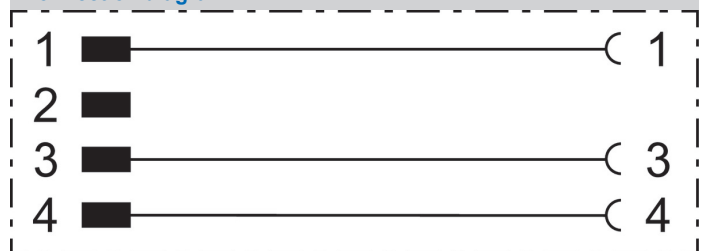

Dimension drawing

