

# CNAC 29H 10-pin Mil Spec Mating Connector + cable L=20 ft (6.10 m)

Article number: 11078427

## Overview

- Shielded connection cable with mating connector NAC 29H 10-pin Mil Spec (female contacts) and stranded wires 0.14 mm<sup>2</sup> with wire end sleeves
- Cable length 20 ft (6.10 m)



## Technical data

### Cable specifications

Weight approx.	440 g
Cable length	20 ft (6.10 m)

### Cable specifications

Operating temperature	-40...+100 °C (fixed cable)
	-30...+100 °C (moved cable)
Outer diameter	≈ 7.0 mm


## Terminal assignment

### Connector with cable sw10, 10-pin

Connector	Core colour	Assignment
Pin A	green	Track A (Track A +)
Pin B	grey	Track B (Track B +)
Pin C	pink	Track Z (Track Z +)
Pin D	red	+Vs
Pin E	violet	$\bar{E}$ rr
Pin F	blue	0 V
Pin G	yellow	Housing
Pin H	brown	Track A inv. (Track A -)
Pin I	black	Track B inv. (Track B -)
Pin J	white	Track Z inv. (Track Z -)

## Suitable for

HS35F, HS35P - Programmable, HS35S - Sine

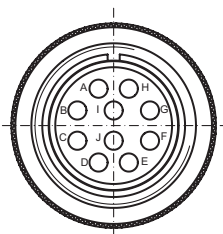

## Dimensions

