

CNAC 29H2500 10-pin Mil Spec Mating Connector

+ cable L=25 m (Stock in US)

Article number: 11150872

Overview

- Shielded connection cable with mating connector NAC 29H 10-pin Mil Spec (female contacts) and stranded wires 0.14 mm² with wire end sleeves
- Cable length 25 m
- Stock in US



Technical data

Cable specifications

Cable length	25 m
Operating temperature	-40...+100 °C (fixed cable) -30...+100 °C (moved cable)

Cable specifications

Outer diameter	≈ 7.0 mm
----------------	----------


Terminal assignment

Connector with cable sw10, 10-pin

Connector	Core colour	Assignment
Pin A	green	Track A (Track A +)
Pin B	grey	Track B (Track B +)
Pin C	pink	Track Z (Track Z +)
Pin D	red	+Vs
Pin E	violet	Err
Pin F	blue	0 V
Pin G	yellow	Housing
Pin H	brown	Track A inv. (Track A -)
Pin I	black	Track B inv. (Track B -)
Pin J	white	Track Z inv. (Track Z -)

Suitable for

HS35F, HS35P - Programmable, HS35S - Sine

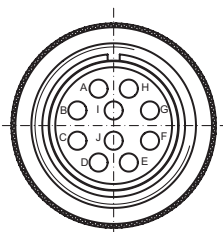

Dimensions

