

Connection cable with FCI, 8-pin / D-SUB, 9-pin,

0.3 m

Article number: 11106562

Overview

- Shielded connection cable with FCI-female coupling (8-pin) and D-SUB-male connector (9-pin)
- UL/CSA certification
- Assembly by customer possible



Technical data

Cable specifications

Weight approx.	80 g
Cable length	0.3 m

Cable specifications


Operating temperature	-40...+100 °C (fixed cable)
	-30...+100 °C (moved cable)
Outer diameter	≈ 7 mm

Terminal assignment

Coupling K21BG8	Coupling K4SG 9
Pin 3	Pin 1
Pin 4	Pin 6
Pin 5	Pin 2
Pin 6	Pin 7
Pin 7	Pin 3
Pin 8	Pin 8
Pin 1	Pin 4
Pin 2	Pin 5
NC	Pin 9
	Shield/Housing

Suitable for

PC-Programming Tool Z-PA-EI-P, Handheld Programming Tool Z-PAEI-H, ATD2AH00, ITD21H00, ITD22H00, ITD22H00 SIL

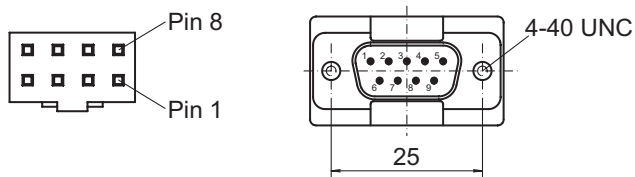

Dimensions

