

Connection cable with FCI, 8-pin / wire end sleeves (UL/CSA), 3 m

Article number: 11092928

Overview

- Shielded connection cable with FCI-female coupling (8-pin) and stranded wires 0.14 mm² with wire end sleeves
- UL/CSA certification
- Assembly by customer possible



Technical data

Cable specifications

 
Weight approx.	195 g
Cable length	3 m

Cable specifications


Operating temperature	-40...+100 °C (fixed cable)
	-30...+100 °C (moved cable)
Outer diameter	≈ 7 mm

Terminal assignment

Connector	Core colour
Pin 1	red
Pin 2	blue
Pin 3	green
Pin 4	brown
Pin 5	grey
Pin 6	black
Pin 7	pink
Pin 8	white
shield = sleeve	transparent



Dimensions

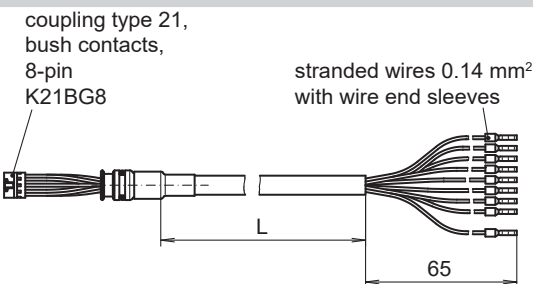

Suitable for

PC-Programming Tool Z-PA-EI-P, Handheld Programming Tool Z-PAEI-H, ATD2AH00, ITD21H00, ITD21H01, ITD22H00, ITD22H00 SIL