


Connection cable with crimp contacts (UL/CSA),

0.2 m

Article number: 11079112

Overview

- Shielded connection cable with stranded wires 0.14 mm² and crimp contacts 61.171.80
- UL/CSA certification
- Assembly by customer possible

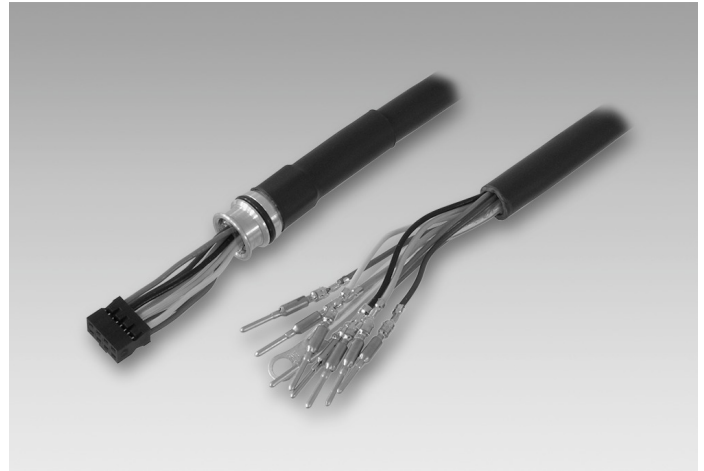

Technical data

Cable specifications


Weight approx.	20 g
Cable length	0.2 m

Cable specifications


Operating temperature	-30...+100 °C (moved cable)
Outer diameter	≈ 7 mm

Terminal assignment

Connector	Core colour
Pin 1	red
Pin 2	blue
Pin 3	green
Pin 4	brown
Pin 5	grey
Pin 6	black
Pin 7	pink
Pin 8	white
shield = sleeve	transparent

 

Dimensions

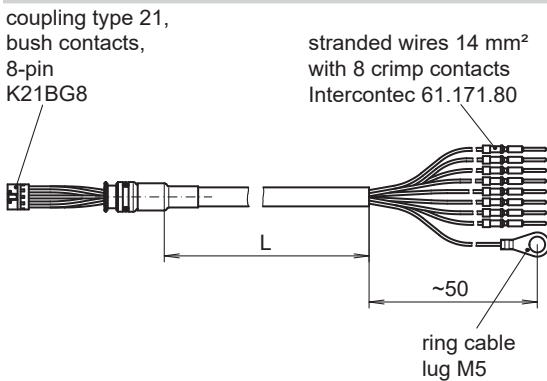

Suitable for

ITD21H00, ITD22H00, ITD22H00 SIL