

Preset counters electromechanic

1 preset, subtracting

Display 5-digits, manual reset button

FS304



FS304 - socket box

Features

- Preset counter with one preset
- Subtracting
- Display 5-digits
- With reset button
- Socket housing

Technical data - electrical ratings

Voltage supply	24/110 VAC $\pm 10\%$ (50/60 Hz) 230 VAC $+6/-10\%$ (50/60 Hz) 24 VDC $\pm 10\%$
Residual ripple	<48 %
Nominal frequency	50 / 60 Hz
Pulse ratio	1:1
Service life	100 million impulses
Preset	1 preset
Output contact	Change-over contact by micro-switch, one-pole
Switching capacity	100 VA / 30 W
Limit switch lifetime	1 million switching cycles
Spark extinguisher	Recommended for inductive load
Standard DIN EN 61010-1	Protection class II Overvoltage category II Pollution degree 2
Emitted interference	DIN EN 61000-6-4
Interference immunity	DIN EN 61000-6-2

Technical data - mechanical design

Display	White numbers on black
Number of digits	5-digits
Digit height	4.5 mm
Count mode	1 impulse = 1 count
Step-by-step switching	Subtracting in 2 half steps
Measuring range	99 999
Zero setting	Manual by reset button
Ambient temperature	0...+45 °C
Storage temperature	-20...+70 °C
Relative humidity	80 % non-condensing
Protection DIN EN 60529	IP 41
Housing type	Socket box
Connection	Soldering pins (flat)
Mounting type	Socket box
Dimensions W x H x L	50 x 50 x 85.9 mm
Cutout dimensions	50 x 50 mm
Mounting depth	85.9 mm
Weight approx.	150 g
Material	Housing: Noryl PPO, black

Preset counters electromechanic

1 preset, subtracting


Display 5-digits, manual reset button

FS304

Trigger level

Count	Voltage DC	Voltage AC
Power	2.2 W	2.4 VA
Min. pulse duration	25 ms	50 ms
Min. pulse interval	25 ms	50 ms
Switch on time (at 25 °C)	100 %	100 %

Connection diagram

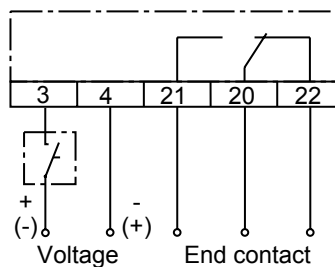

Accessories

Front panels

10125138 Front panel with transparent protective cover, for socket box 50 x 50 mm (Z 100.02A)

Front frames

10124120 Front frame with knob lock provided on transparent cover (Z 102.01A)

11034050 Front frame with cylinder lock provided on transparent cover (Z 102.02A)

10125089 Front frame, insertion cutout 50 x 50 mm (Z 107.02A)

Preset counters electromechanic

1 preset, subtracting

Display 5-digits, manual reset button

FS304

Part number

FS304.

550A		B
------	--	---

Display
B 5-digits 99999

Voltage
A3 24 VDC
A5 24 VAC
A8 110 VAC
A9 230 VAC

Zero setting
550A With reset button

Preset counters electromechanic

1 preset, subtracting

Display 5-digits, manual reset button

FS304

Dimensions

