

## Overview

- pulsed red LED
- PNP
- Teach-in
- connector M12 5 pin
- -25 ... 55 °C
- IP 65



Picture similar



## Technical data

### General data

Version	Integrated alarm output
Sensing distance Tw (FUE 200C1003)	90 mm
Light source	Pulsed red LED
Light indicator	LED green
Alignment / soiled lens indicator	LED green, flashing
Output indicator	LED yellow
Adjustment	Teach-in
Wave length	660 nm
Suppression of reciprocal influence	Yes

### Electrical data

Response time / release time	< 1 ms
Voltage supply range +Vs	10 ... 30 VDC
Current consumption max. (no load)	68 mA

### Electrical data

Current consumption typ.	50 mA
Voltage drop Vd	<1.8 VDC
Output function	Light / dark operate switchable
Min. output pulse length	40 ms
Output circuit	PNP
Output current	100 mA
Short circuit protection	Yes
Reverse polarity protection	Yes


### Mechanical data

Width / diameter	22 mm
Height / length	33.2 mm
Depth	60 mm
Design	Rectangular
Housing material	PBT / PC
Connection types	Connector M12 5 pin


### Ambient conditions

Operating temperature	-25 ... +55 °C
Protection class	IP 65

## Dimension drawing

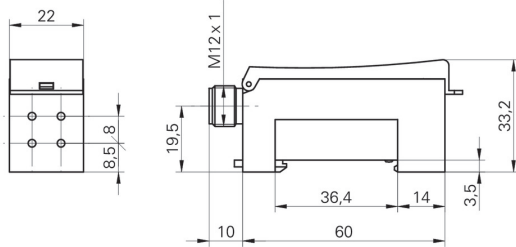

## Connection diagram

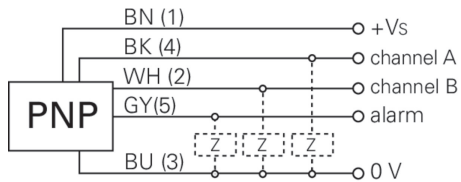

## Accessories

### Mounting accessories

10125534

10125534