
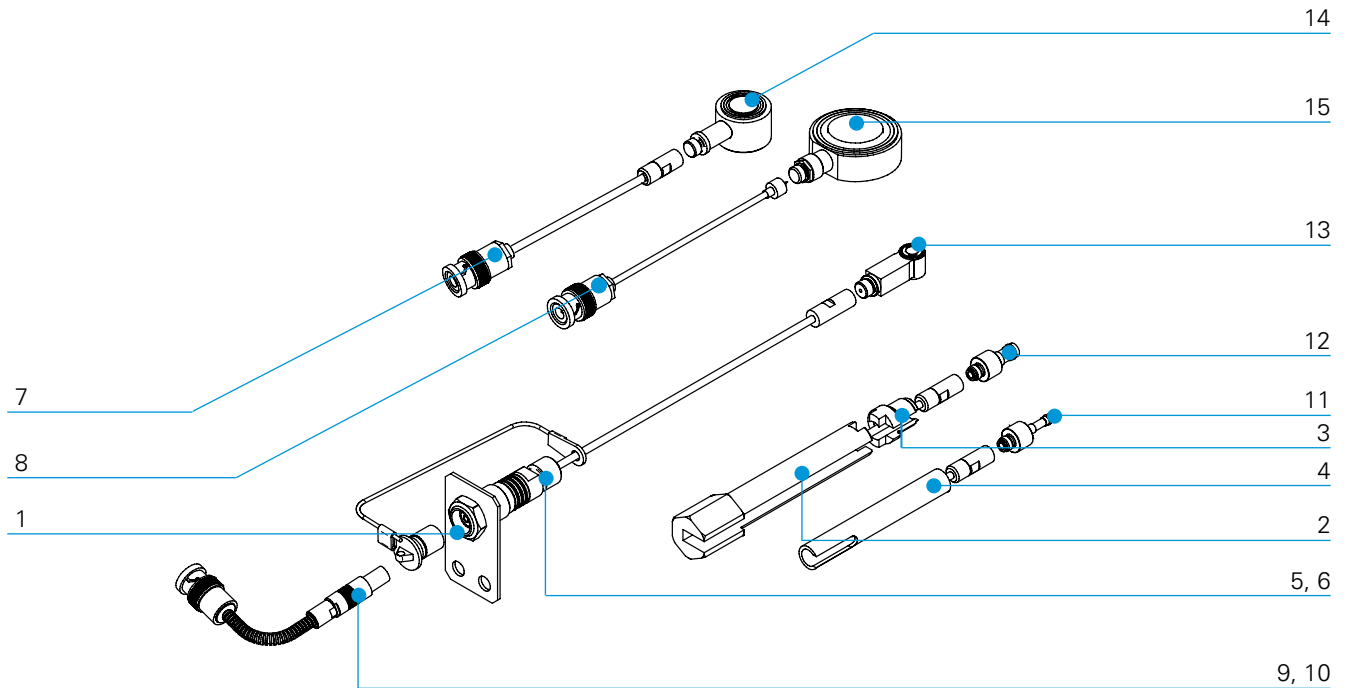


# Summary Accessories and Sensors

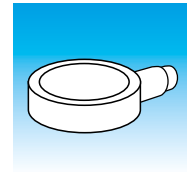


Pos.	Mounting Accessories	Type
1	Mounting equipment Fischer connector	DZPC HPFC
2	Mounting wrench	DZPC MWPT
3	Special nut for 2,5 / 4 mm cavity pressure sensor	DZPC MN04
4	Spacer tube for 2,5 / 4 mm cavity pressure sensor	DZPC MT04

Pos.	Cable	Type
5	Sensor cable 0...+200 °C M4 x 0,35 - Fischer	DZCC ... -ST-MF
6	Sensor cable 0...+220 °C M4 x 0,35 - Fischer	DZCC ... -HT-MF
7	Sensor cable M4 x 0,35 - BNC	DZCC ... -ST-MB
8	Sensor cable UNF 10-32 - BNC	DZCC ... -78-UB
9	Connecting cable Fischer - BNC	DZCC ... -04-FB
10	Connecting cable Fischer - BNC with protecting tube	DZCC ... -HT-FB


Pos.	Sensors	Type
11	Cavity pressure sensor ø 2,5 mm	DPPC DS02.5-2.0
12	Cavity pressure sensor ø 4,0 mm	DPPC DS04.0-x.x
13	Miniature force sensor 2,5 kN	DLPP 6MO-2.5-4.4
14	Force sensor 10 kN	DLPP 7MO-010-2.2
15	Force sensor 30 kN	DLPP 4MO-030-4.4

# Mounting Accessories

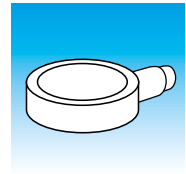

## DZPC MWPT


Mounting wrench for DPPC DS02.5  
DPPC DS04.0

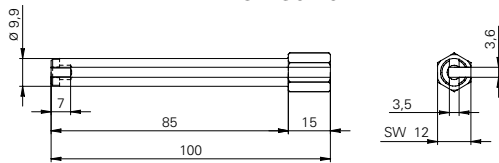

Mat.: 1.4305

## DZPC HPFC


Mounting plate Fischer connector

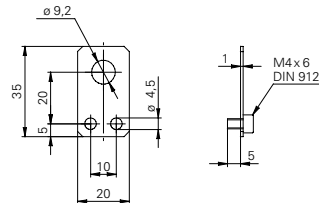

Mat.: 1.4305

## DZPC MN04

Special nut for DPPC DS02.5  
DPPC DS04.5

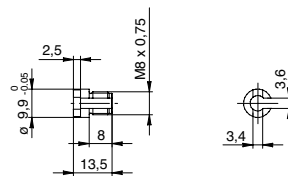


Mat.: 1.4305

## DZPC MT04

Spacer tube for DPPC DS02.5 (MT04)  
DPPC DS04.0 (MT04)




Mat.: 1.4305

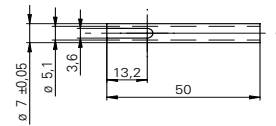


# Cables

## DZCC

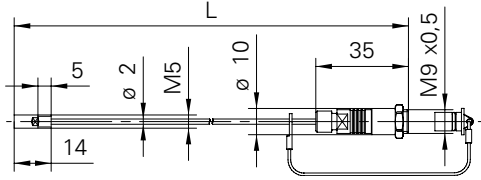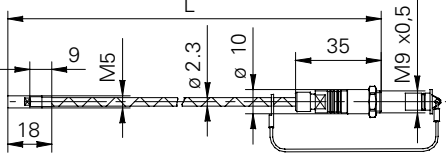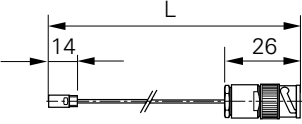

Sensor Cable		DZCC ...- ST-MF	
<b>L [mm]</b>	<b>Order code</b>	Connector	Connector
200	DZCC 0200-ST-MF	M4 x 0,35	
400	DZCC 0400-ST-MF		
600	DZCC 0600-ST-MF		
1000	DZCC 1000-ST-MF		
Custom length	DZCC xxxx-ST-MF		
<b>Technical data</b>			
Cable	Coax, Low Noise, PTFE/PFA	Delivery contents • Mounting plate Fischer connector DZPC HPFC	
Color	blue		
Impedance	50 Ω		
Cable-ø	2 mm		
Bending radius	R5		
Operating temp. range	0...+200°C		
		Fischer Type KE 102 A014	
Sensor Cable		DZCC ...- HT-MF	
<b>L [mm]</b>	<b>Order code</b>	Connector	Connector
200	DZCC 0200-HT-MF	M4 x 0,35	
400	DZCC 0400-HT-MF		
600	DZCC 0600-HT-MF		
1000	DZCC 1000-HT-MF		
Custom length	DZCC xxxx-HT-MF		
<b>Technical data</b>			
Cable	Coax, Low Noise, PTFE/PFA	Delivery contents • Mounting plate Fischer connector DZPC HPFC	
Color	steel sheathed		
Impedance	50 Ω		
Cable-ø	2, 4 mm		
Bending radius	R8		
Operating temp. range	0...+220°C		
		Fischer Type KE 102 A014	
Sensor Cable		DZCC ...- ST-MB	
<b>L [mm]</b>	<b>Order code</b>	Connector	Connector
1000	DZCC 1000-ST-MB	M4 x 0,35	
2000	DZCC 2000-ST-MB		
Custom length	DZCC xxxx-ST-MB		
<b>Technical data</b>		BNC	
Cable	Coax, Low Noise, PTFE/PFA		
Color	blue		
Impedance	50 Ω		
Cable-ø	1,9 mm		
Bending radius	R5		
Operating temp. range	0...+200°C		

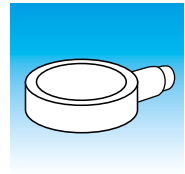

Sensor Cable		DZCC ...-78-UB	
<b>L [mm]</b>	<b>Order code</b>	Connector	Connector
1000	DZCC 1000-78-UB	UNF 10 - 32	
2000	DZCC 2000-78-UB		
3000	DZCC 3000-78-UB		
Tailor made	DZCC xxxx-78-UB		
<b>Technical data</b>			
Cable	Coax 178 RG		
Color	brown		
Impedance	50 Ω		
Cable-ø	1,8 mm		
Bending radius	R10		
Operating temp. range	0...+200°C		
Connector			BNC
Connecting Cable		DZCC ...-04-FB	
<b>L [mm]</b>	<b>Order code</b>	Connector	Connector
2000	DZCC 2000-04-FB	Fischer Type S 102 A014	
4000	DZCC 4000-04-FB		
5000	DZCC 5000-04-FB		
Custom length	DZCC xxxx-04-FB		
<b>Technical data</b>			
Cable	Triax, Low Noise, PTFE/PFA		
Color	transparent		
Impedance	50 Ω		
Cable-ø	3,4 mm		
Bending radius	R10		
Operating temp. range	0...+200°C		
Connector			BNC
Connecting Cable DZCC ...-HT-FB		DZCC ...-HT-FB	
<b>L [mm]</b>	<b>Order code</b>	Connector	Connector
2000	DZCC 2000-HT-FB	Fischer Type S 102 A014	
4000	DZCC 4000-HT-FB		
5000	DZCC 5000-HT-FB		
Custom length	DZCC xxxx-HT-FB		
<b>Technical data</b>			
Cable	Triax, Low Noise, PTFE, PFA		
Color	metal sheath		
Impedance	50 Ω		
Cable-ø	5 mm		
Bending radius	R30		
Operating temp. range	0...+220 °C		
Connector			BNC