


Sensortester Analog

Mat.-No.: 11084376

Drawing

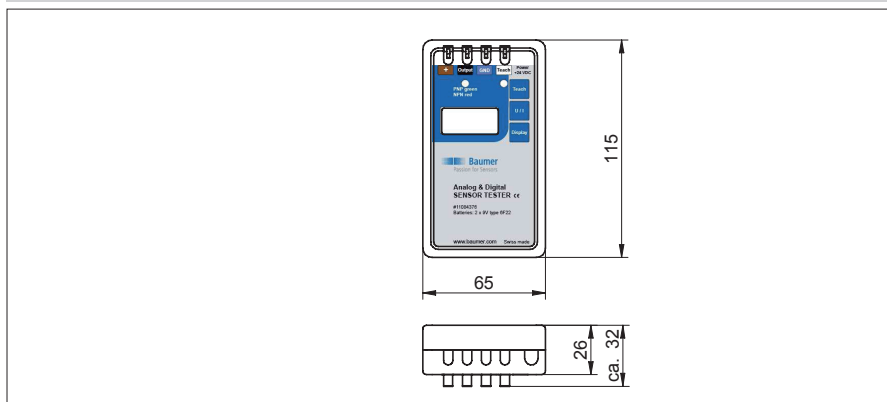

General data

ON NPN	LED red
ON PNP	LED green
Analog display	0 ... 10 V, 4 ... 20 mA
Teach-in of the Sensor	integrated button on the sensor tester

Functions

Recognizing of the sensor type (NPN / PNP)	
Status of the sensor output	
Measurement of the analog output	0 ... 10 V, 4 ... 20 mA

Electrical data

Supply of the sensor tester	2 * 9 V battery type 6F22, possibility for power supply unit as an accessory
Supply of sensors	18 V / 50 mA (Battery), 24 V / 300 mA (Power supply unit)
Power consumption	Display on, LED on, without sensor < 20 mA, with Sensor: depends on the sensor type
Battery life	7h at 50 mA

Mechanical data

Housing material	ABS
Length	115 mm
Width	65 mm
Height	26 mm