


Connector with attached PVC-cable

dimension drawing

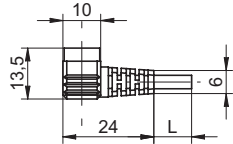

- 2-wire
- Snap-in
- external sheath PVC
- for My Com BS

General data

cable type	PVC blue
conductor cross section	2 x 0,14 mm ²
conductor structure, signal line	72 x 0,05 mm
cable diameter	3,6 ± 0,2 mm
external sheath, color	blue RAL 5015
wire colors	blue, black
operating temperature movable installation	-5°C bis +70°C
operating temperature fixed installation	-25°C bis +70°C
bending radius	36 mm movable installation
resistant	30 min. resistant to spiritus

type Mat.-No. L

angular connectors

KSW 30BV0200	10258354	2 m
KSW 30BV0500	10225298	5 m

pin assignment

