


# Connection cable with FCI, 8-pin / wire end sleeves (UL/CSA), 1 m

Article number: 11072169

## Overview

- Shielded connection cable with FCI-female coupling (8-pin) and stranded wires 0.14 mm<sup>2</sup> with wire end sleeves
- UL/CSA certification
- Assembly by customer possible

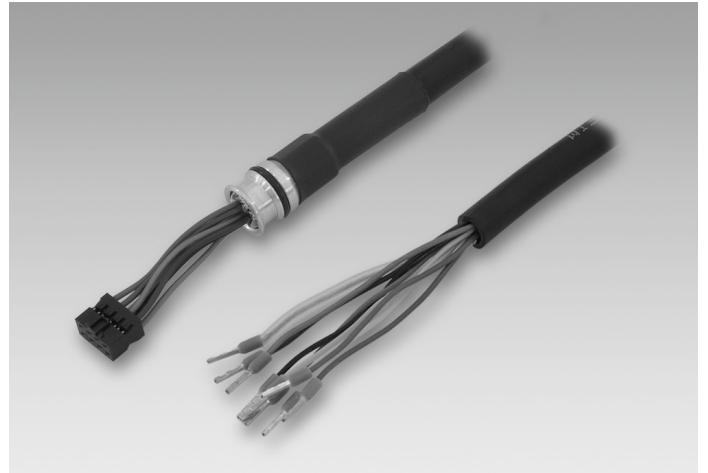

## Technical data

### Cable specifications

 
Weight approx.	70 g
Cable length	1 m

### Cable specifications


Operating temperature	-40...+100 °C (fixed cable)
	-30...+100 °C (moved cable)
Outer diameter	≈ 7 mm

## Terminal assignment

Connector	Core colour
Pin 1	red
Pin 2	blue
Pin 3	green
Pin 4	brown
Pin 5	grey
Pin 6	black
Pin 7	pink
Pin 8	white
shield = sleeve	transparent



## Dimensions

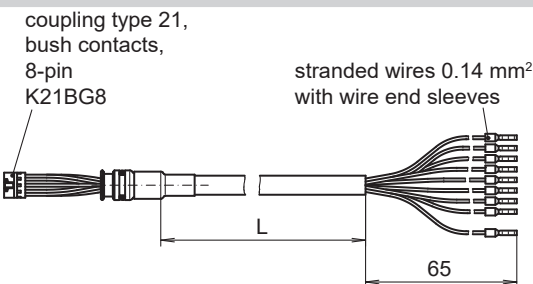

## Suitable for

PC-Programming Tool Z-PA-EI-P, Handheld Programming Tool Z-PA-EI-H, ATD2AH00, ITD21H00, ITD21H01, ITD22H00, ITD22H00 SIL