

CNAC 25E 7-pin Mil Spec Mating Connector + cable

L=10 ft (3.05 m)

Article number: 11078440

Overview

- Shielded connection cable with mating connector NAC 25E 7-pin Mil Spec (female contacts) and stranded wires 0.14 mm² with wire end sleeves
- Cable length 10 ft (3.05 m)



Technical data

Cable specifications

Weight approx.	250 g
Cable length	10 ft (3.05 m)


Cable specifications

Operating temperature	-40...+100 °C (fixed cable)
	-30...+100 °C (moved cable)
Outer diameter	≈ 7.0 mm


Terminal assignment

Connector with cable sw10, 7-pin

Connector	Core colour	Assignment
Pin A	green	Track A
Pin B	grey	Track B
Pin C	pink	Track Z
Pin D	red	+Vs
Pin E	–	–
Pin F	blue	0 V
Pin G	yellow	Housing

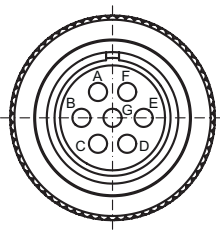

Dimensions

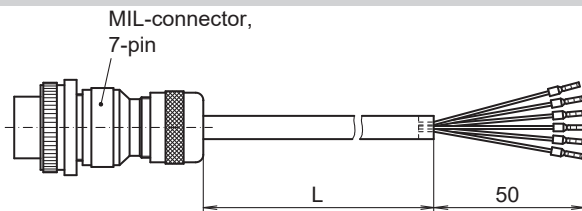

Suitable for

HS35F, HS35P - Programmable