

# CNAC 25E1000 7-pin Mil Spec Mating Connector + cable L=10 m (Stock in US)

Article number: 11150865

## Overview

- Shielded connection cable with mating connector NAC 25E 7-pin Mil Spec (female contacts) and stranded wires 0.14 mm<sup>2</sup> with wire end sleeves
- Cable length 10 m
- Stock in US



## Technical data

### Cable specifications

Cable length	10 m
Operating temperature	-40...+100 °C (fixed cable) -30...+100 °C (moved cable)


### Cable specifications

Outer diameter	≈ 7.0 mm
----------------	----------


## Terminal assignment

### Connector with cable sw10, 7-pin

Connector	Core colour	Assignment
Pin A	green	Track A
Pin B	grey	Track B
Pin C	pink	Track Z
Pin D	red	+Vs
Pin E	–	–
Pin F	blue	0 V
Pin G	yellow	Housing

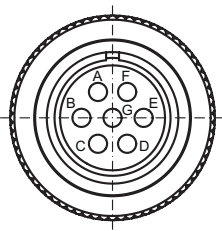

## Dimensions

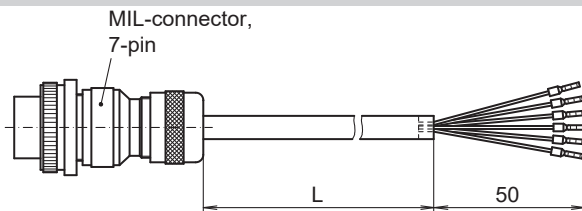

## Suitable for

HS35F, HS35P - Programmable