

# Shielded cable 3 wires, 10,0 m

Article number: 11002561

## Overview

- shielded power cable
- M8/3-pin female connector to open wires
- cable carrier compatible
- length 10,0 m



*Picture similar*

## Technical data

### Electrical data

Shielding	yes
Number of poles	3
Connectors	M8 female connector, screw lock open wires

### Mechanical data

Smallest bending radius moved installation	46 mm
Use in cable carriers	yes
Cable length [m]	10 m
Weight	≤ 345 g

### Mechanical data

Material	PUR
----------	-----


### Interface

Data interface	Process interface
----------------	-------------------

### Environmental conditions

Flame resistance	VDE0472 part 804/B
Resistance to oil	VDE 0472 part 803
Operation temperature (static)	-50 ... +80 °C
Protection class	IP 67 (camera side)

## Pin assignment

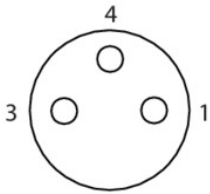

---

M8	color
----	-------

---

1:	BN
----	----

---

4:	BK
----	----

---

3:	BU
----	----

---