


Z-ESG 32DH0500G

Shielded cable 6 wires, 5,0 m

Article number: 11098904

Overview

- shielded process interface and power cable for Baumer *VisiLine*® cameras
- M8/6-pin female connector to open wires
- cable carrier compatible
- length 5,0 m

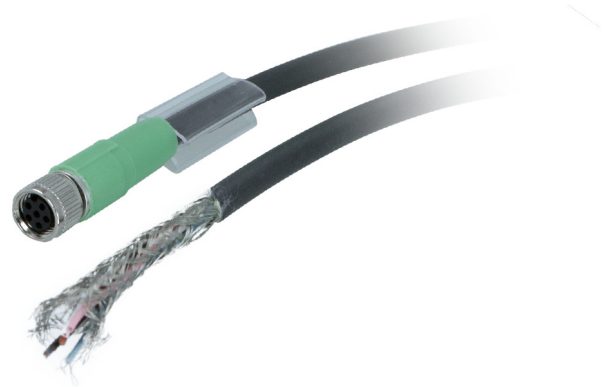

Picture similar

Technical data

Electrical data

Shielding	yes
Number of poles	6
Connectors	M8 female connector, screw lock

Mechanical data

Smallest bending radius static	52 mm
Smallest bending radius moved installation	52 mm
Bending cycles	4000000
Use in cable carriers	yes
Cable length [m]	5 m

Mechanical data

Weight	≤ 187 g
Material	PUR, halogen-free

Interface

Data interface	Process interface
----------------	-------------------

Environmental conditions


Flame resistance	DIN UL-Style 20549
Halogen-free	DIN VDE 0472 part 815
Resistance to oil	DIN EN 60811-2-1
Operation temperature (static)	-5 ... +80 °C
Protection class	IP 65/67 (camera side)

Z-ESG 32DH0500G

Shielded cable 6 wires, 5,0 m

Article number: 11098904

Pin assignment

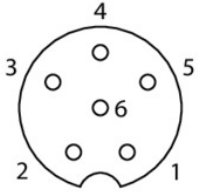

M8	color	M8	color
1:	BN	4:	BK
2:	WH	5:	GY
3:	BU	6:	PK