


Z-ESG 32DH1000G

Shielded cable 6 wires, 10,0 m

Article number: 11105006

Overview

- shielded process interface and power cable for Baumer *VisiLine*® cameras
- M8/6-pin female connector to open wires
- cable carrier compatible
- length 10,0 m

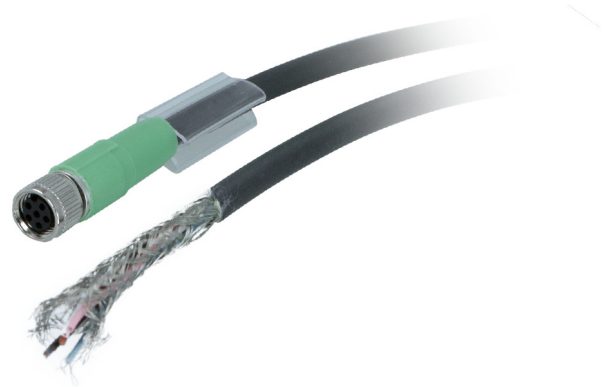

Picture similar

Technical data

Electrical data

| | |
|-----------------|---------------------------------|
| Shielding | yes |
| Number of poles | 6 |
| Connectors | M8 female connector, screw lock |

Mechanical data

| | |
|--|---------|
| Smallest bending radius static | 52 mm |
| Smallest bending radius moved installation | 52 mm |
| Bending cycles | 4000000 |
| Use in cable carriers | yes |
| Cable length [m] | 10 m |

Mechanical data

| | |
|----------|-------------------|
| Weight | ≤ 382 g |
| Material | PUR, halogen-free |

Interface

| | |
|----------------|-------------------|
| Data interface | Process interface |
|----------------|-------------------|

Environmental conditions


| | |
|--------------------------------|------------------------|
| Flame resistance | DIN UL-Style 20549 |
| Halogen-free | DIN VDE 0472 part 815 |
| Resistance to oil | DIN EN 60811-2-1 |
| Operation temperature (static) | -5 ... +80 °C |
| Protection class | IP 65/67 (camera side) |

Z-ESG 32DH1000G

Shielded cable 6 wires, 10,0 m

Article number: 11105006

Pin assignment

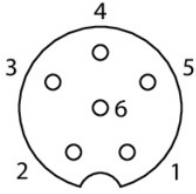

| M8 | color | M8 | color |
|----|-------|----|-------|
| 1: | BN | 4: | BK |
| 2: | WH | 5: | GY |
| 3: | BU | 6: | PK |