

Z-ESG 32FP0500G

Shielded cable 8 wires, female connector, 5,0 m

Article number: 11118810

Overview

- shielded process interface cable
- M8/8-pin female connector to open wires
- cable carrier compatible
- length 5,0 m



Picture similar

Technical data

Electrical data

Shielding	yes
Number of poles	8
Connectors	M8 female connector, screw lock

Mechanical data

Smallest bending radius static	29.5 mm
Smallest bending radius moved installation	59 mm
Bending cycles	2000000
Use in cable carriers	yes
Cable length [m]	5 m
Weight	≤ 246 g
Material	PUR, halogen-free

Interface

Data interface	Process interface
----------------	-------------------

Environmental conditions


Flame resistance	DIN EN 60332-1-2 VDE 0482-332-1-2 IEC 60332-1-2 CSA FT-2
Halogen-free	DIN EN 50267-2-1 IEC 60754-1 VDE 0482-267-2-1
Resistance to oil	DIN EN 60811-2-1, 168 h at 100°C
Operation temperature (static)	-50 ... +80 °C
Protection class	IP 65/67 (camera side)

Z-ESG 32FP0500G

Shielded cable 8 wires, female connector, 5,0 m

Article number: 11118810

Pin assignment

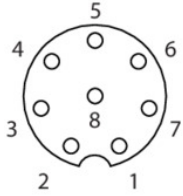

M8	wire color	M8	wire color
1:	WH	5:	GY
2:	BN	6:	PK
3:	GN	7:	BU
4:	YE	8:	RD