


Z-ESW 31FH0500

90° Cable 8 wires, 5,0 m

Article number: 11105262

Overview

- process interface cable
- 90° angled M8/8-pin female connector to open wires
- length 5,0 m
- alternative article: CAM8.A8-11232605

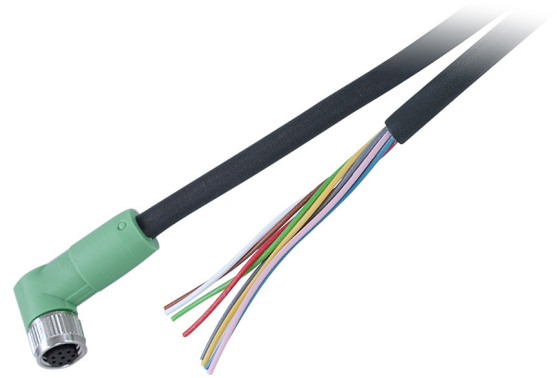

Picture similar

Technical data

Electrical data

Shielding	no
Number of poles	8
Connectors	M8 female connector, angled, screw lock

Mechanical data

Smallest bending radius static	26 mm
Smallest bending radius moved installation	52 mm
Use in cable carriers	no
Cable length [m]	5 m
Weight	≤ 175 g

Mechanical data

Material	PUR
----------	-----

Interface

Data interface	Process interface
----------------	-------------------

Environmental conditions


Flame resistance	UL 758/1581 (horizontal) UL 758/1581 FT2
Halogen-free	DIN VDE 0472 part 815 DIN EN 50267-2-1
Resistance to oil	DIN EN 60811-2-1, 168 h at 100°C
Operation temperature (static)	-25 ... +80 °C
Protection class	IP 65/67/68 (camera side)

Z-ESW 31FH0500

90° Cable 8 wires, 5,0 m

Article number: 11105262

Pin assignment

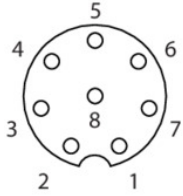

M8	wire color	M8	wire color
1:	WH	5:	GY
2:	BN	6:	PK
3:	GN	7:	BU
4:	YE	8:	RD