

Vue d'ensemble

- Male straight
- M12 , 5-pole, A-coded
- max. 0,75mm², 4 - 6mm, shielded




Caractéristiques techniques

Side A	
Head A: Connection	M12
Head A: Angle cable outlet	0°
Head A: Gender	Male
Head A: Coding	A
Head A: Shielded	Oui
Head A: No. of poles	5
Head A: Tightening torque	0,6 Nm
Head A: Knurled nut material	GD-Zn,Ni
Head A: Body color	Black
Head A: Gasket material	Elastomer
Max. AWG	18
Connection method	Screw terminals

Side A	
Wire cross section (max.)	0,75 mm ²
Cable diameter (max.)	6 mm
Cable diameter (min.)	4 mm
Données électriques	
Operating voltage	max. 50 V AC/DC 0
Operating current per contact	max. 4 A
Données mécaniques	
Head A: Degree of protection	IP67
Conditions ambiantes	
Head A: Pollution degree	3
Commercial data	
Eclass	27440102

Side A

Technical drawing

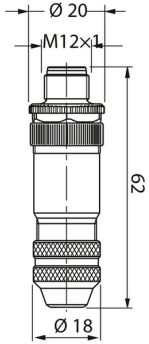

Coding

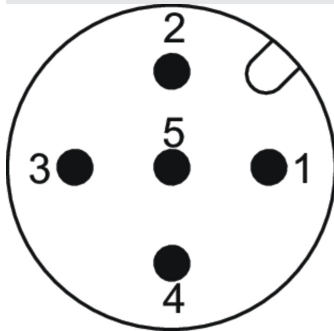


Schéma de raccordement

