 


Vue d'ensemble

- Male straight
- M12 , 5-pole, A-coded
- max. 0,75mm², 6 - 8mm, shielded




Caractéristiques techniques

Side A		Side A	
Head A: Connection	M12	Wire cross section (max.)	0,75 mm ²
Head A: Angle cable outlet	0°	Cable diameter (max.)	8 mm
Head A: Gender	Male	Cable diameter (min.)	6 mm
Head A: Coding	A	Données électriques	
Head A: Shielded	Oui	Operating voltage	max. 50 V AC/DC 0
Head A: No. of poles	5	Operating current per contact	max. 4 A
Head A: Width across flats	AF18	Données mécaniques	
Head A: Tightening torque	0,6 Nm	Head A: Degree of protection	IP67
Head A: Knurled nut material	GD-Zn,Ni	Conditions ambiantes	
Head A: Body color	Black	Head A: Pollution degree	3
Head A: Gasket material	Elastomer	Commercial data	
Max. AWG	20	Eclass	27440102
Connection method	Screw terminals		

Side A

Technical drawing

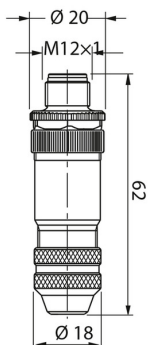

Coding

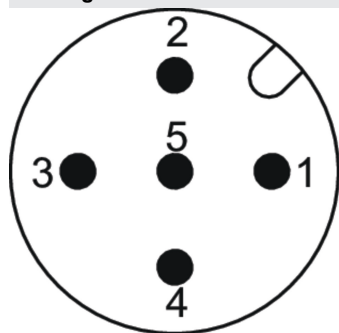


Schéma de raccordement

