

Vue d'ensemble

- Female straight
- M12 , 8-pole, A-coded
- max. 0,5mm² ,6 - 8mm, shielded




Caractéristiques techniques

Side A	
Head A: Connection	M12
Head A: Angle cable outlet	0°
Head A: Gender	Female
Head A: Coding	A
Head A: Shielded	Oui
Head A: No. of poles	8
Head A: Tightening torque	0,6 Nm
Head A: Knurled nut material	GD-Zn,Ni
Head A: Gasket material	Elastomer
Max. AWG	20
Connection method	Screw terminals
Wire cross section (max.)	0,5 mm ²

Side A	
Cable diameter (max.)	8 mm
Cable diameter (min.)	6 mm
Données électriques	
Operating voltage	max. 30 V AC/DC 0
Operating current per contact	max. 2 A
Données mécaniques	
Head A: Degree of protection	IP67
Conditions ambiantes	
Head A: Pollution degree	3
Commercial data	
Eclass	27440102

Side A

Technical drawing

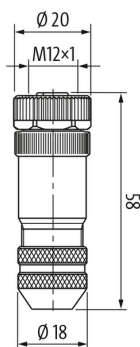

Side A

Coding

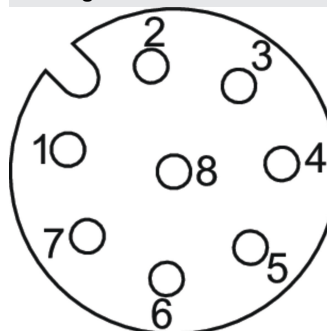


Schéma de raccordement

